

POWR-GARD® Fuse Datasheet

Box Cover Units



Description

Provide economical method of protecting small motors against overcurrent damage.

Applications

- Edison-Base plug fuses (TOO, TLO)
- Type S plug fuses (SOO, SLO) with adapters (SAO)

Specifications

Voltage Rating	125 V
Max Amperage Rating	15 A
Approvals	UL Listed parts (Except LSSYRL)

Web Resources

Sample requests, downloadable CAD drawings and other technical information: www.littelfuse.com/boxcover

 


Figure 1

 


Figure 2

 


Figure 3

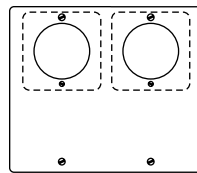


Figure 4

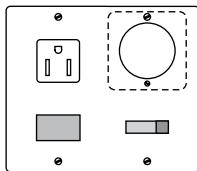


Figure 5

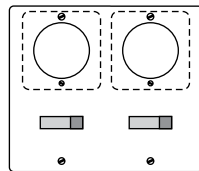


Figure 6

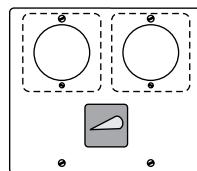


Figure 7

POWR-GARD® Fuse Datasheet

Box Cover Units

FIGURE NUMBER	LITTELFUSE PART NUMBER	BOX COVER FEATURES					TO BE MOUNTED ON
		EDISON BASE FUSE HOLDER	GROUNDING RECEPTACLE	SINGLE POLE SWITCH	TWO POLE SWITCH	PILOT LIGHT	
1	LSOU	1	—	—	—	—	2-1/4" Handy Box
2	LSRU*	1	1	—	—	—	2-1/4" Handy Box
	LSRW	1	1	—	—	—	2-3/4" Switch Box
	LSRY	1	1	—	—	—	4" Square Box
3	LSSU*	1	—	1	—	—	2-1/4" Handy Box
	LSSW	1	—	1	—	—	2-3/4" Switch Box
	LSSY*	1	—	1	—	—	4" Square Box
4	LSOYB	2	—	—	—	—	4" Square Box
5	LSSYRL	1	1	1	—	1	4" Square Box
6	LSCY	2	—	2	—	—	4" Square Box
7	LSTY	2	—	—	1	—	4" Square Box

*UL Listed (File No. E308725)

Disclaimer Notice – Information furnished is believed to be accurate and reliable. However, users should independently evaluate the suitability of and test each product selected for their own applications. Littelfuse products are not designed for, and may not be used in, all applications. Read complete Disclaimer Notice at www.littelfuse.com/product-disclaimer.