

# 150 Mini Series


## In-Line Fuseholder

**HF** **RoHS** **Pb**


### Product Characteristics

<b>Compatible Fuses</b>	Mini Blade Fuse or Type F Fuse
<b>Electrical Specifications</b>	Rated Voltage: 32 V Rated Current: From 20 A to 30 A
<b>Terminals</b>	Copper Alloy Tin Plated
<b>Body</b>	Black Thermoplastic
<b>Ambient Temperature</b>	-40 °C to 105 °C
<b>Crimping Tool</b>	Ideal #30-428 toothed die slot or equivalent. Crimp the matted area to secure the wire.

### Product Dimensions

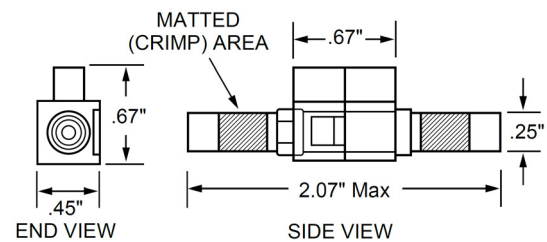

### Additional Information



Resources



Accessories



Samples

### Ordering Information

Ordering PN	Current	Voltage	Terminal Material	Plating	Wire Range AWG	Packaging
01530002H	20 A	32 V	Copper Alloy	Tin Plated	16-22	100 pcs (bulk)
01530003H	30 A	32 V	Copper Alloy	Tin Plated	10-14	100 pcs (bulk)

**Disclaimer Notice** - Information furnished is believed to be accurate and reliable. However, users should independently evaluate the suitability of and test each product selected for their own applications. Littelfuse products are not designed for, and may not be used in, all applications. Read complete Disclaimer Notice at <http://www.littelfuse.com/disclaimer-electronics>.