

# Certificate



Certificate no.

T 50260582 01

**License Holder:**  
Suzhou Littelfuse OVS Ltd  
6 Xinghai Street  
Suzhou Industrial Park  
Suzhou, Jiangsu 215021  
P.R. China

**Manufacturing Plant:**  
Suzhou Littelfuse OVS Ltd  
6 Xinghai Street  
Suzhou Industrial Park  
Suzhou, Jiangsu 215021  
P.R. China

**Test report no.:** ZTW2-KSH 15060184 002

**Client Reference:** W.W.

**Tested to:** UL 248-1:2011  
UL 248-14:2010

**Certified Product:** (Cartridge Fuses)

**License Fee - Units**

Type Designation : 328021  
Rated Voltage : AC 300V or DC 100V  
Rated Frequency : 50/60Hz  
Rated Current : 21A  
Rated Breaking Capacity : 200A at 300VAC, pf=1,0  
200A at 100VDC, t<0,02ms  
Dimension : 6,35mm\*31,75mm  
(with or without pigtail)

5


**Remark:**  
More information refer to Appendix 1.

**Appendix:** 1



5

**Licensed Test mark:**

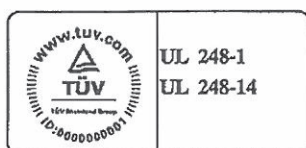

**TÜV Rheinland Taiwan Ltd.**

Signature

Dipl.-Ing. W. Feuker

**Date of Issue**

(day/mo/yr)

16/07/2013

# Certificate



Certificate no.

T 50260582 02

**License Holder:**

Littelfuse Inc.  
O'Hare Plaza II Ste 500  
8755 W. Higgins Rd.  
Chicago, IL 60631  
USA

**Manufacturing Plant:**

Suzhou Littelfuse OVS Ltd  
6 Xinghai Street  
Suzhou Industrial Park  
Suzhou, Jiangsu 215021  
P. R. China

Test report no.: KSH 15060184 003

Client Reference: B.T.

Tested to: UL 248-1:2011  
UL 248-14:2010

Certified Product: (Miniature fuse-link#

License Fee - Units

as page 0001

Change

Name of License Holder : See above

Address of License Holder : See above




Licensed Test mark:

TÜV Rheinland (China) Ltd.

Signature

Date of Issue  
(day/mo/yr)

19/03/2018

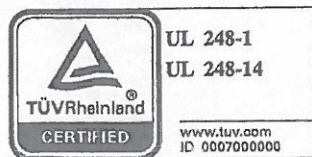

*Zhao Xinhua*  
Zhao Xinhua

TÜV Rheinland (China) Ltd

No. 01/03B-08, Floor 7 and No. 01/04B-08, Floor 11, AVIC Building, No.10B, Central Road, East 3rd Ring Road,  
Chaoyang District, Beijing, P.R. China