


RATINGS:

MAXIMUM VOLTAGE	22,000 Vac
MAXIMUM CURRENT	220 mA
RESISTANCE	100 kΩ
THERMAL	
22,000 Vac	1 MINUTE ON
	120 MINUTES OFF
3,000 Vac	CONTINUOUS
TORQUE	
TERMINAL N	9.0 N-m (80 in-lb)

- NOTES:
1. DIMENSIONS IN MILLIMETERS [INCHES]
 2. TERMINAL-BLOCK SCREWS: 6-32 x 0.5
 3. MOUNTING SCREWS: M6 OR 0.25-20
 4. USE LIQUID-TIGHT FITTING FOR TERMINAL BLOCK ENCLOSURE CABLE ENTRY.
 5. MOUNT AS SHOWN WITH BASE HORIZONTAL.
 6. CERTIFICATIONS NOT SHOWN.

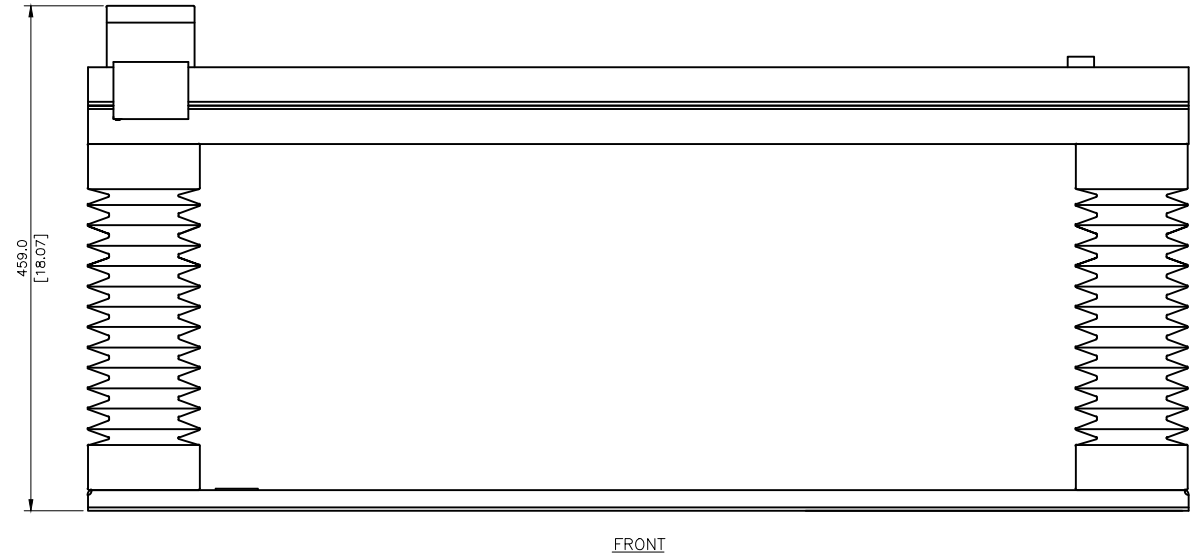