 
 
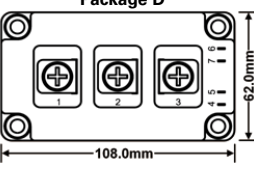
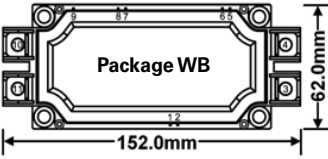
 
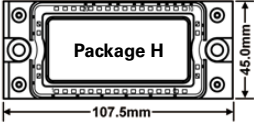
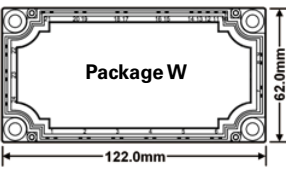
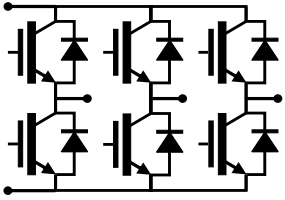
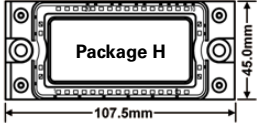
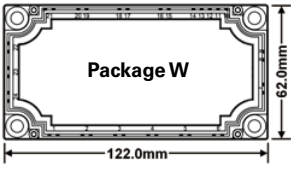

 

 


CIRCUIT TYPE	PACKAGE TYPE	COLLECTOR EMITTER VOLTAGE (V)	RATING (A)					
<b>IGBT MODULE</b>								
Half-bridge 	<b>Package S</b>  94x33.8x30.5mm	600			100		150	200
		1200	50	75	100	105	150	
		1700	50	75	100			
	<b>Package D</b>  108x62x30.5mm	600					300	400
		1200	100	150	200		300	400
		1700	100	150	200		300	
	<b>Package WB</b>  152x62x17mm	600					600	
		1200	225	300			450	
		1700	225	300			450	

CIRCUIT TYPE	PACKAGE TYPE	COLLECTOR EMITTER VOLTAGE (V)	RATING (A)					
<b>IGBT MODULE</b>								
3-phase Converter Brake Inverter Module 	<b>Package H</b>  107.5x45x17mm	1200	15	25	40			
	<b>Package W</b>  122x62x17mm					50	75	

CIRCUIT TYPE	PACKAGE TYPE	COLLECTOR EMITTER VOLTAGE (V)	RATING (A)				
<b>IGBT MODULE</b>							
3-phase Inverter Module (6 Pack) 	 Package H 107.5x45x17mm	1200	25	50	75		
	 Package W 122x62x17mm					75	100

CIRCUIT TYPE	PACKAGE TYPE	COLLECTOR EMITTER VOLTAGE (V)	RATING (A)				
<b>RECTIFIER DIODE MODULE</b>							
Phase Leg 	 Package A 93x21x30.4mm	1600	90	110			
			1800	90	110		
Common Cathode 	 Package S 94x33.8x30.5mm	1600	130	160	180	200	
			1800	130	160	180	200