

150HV Series

Heavy Duty In-line Holder for 3AB/AG



Product Characteristics

Compatible Fuses	3AB/AG Fuses
Electrical	Intended for use at 600 VAC/DC max rated up to 20 amperes.*
Molded Parts	Body and knob are Black Thermoset (UL94 V-0). Both body and knob have a 0.20" diameter hole for insulated wire.
Knob	Bayonet-lock type metal insert.
Ambient Temperature	-40°C to + 85°C
Contact Rivet	Brass. Tin plated
Assembled	Supplied with 19" loop of #14 AWG red vinyl insulated wire

Notes:

* Refer to [Fuseology](#) for information on proper fuseholder re-rating.

Agency Approval

Agency	Agency File Number
cULus	E14721 *

Notes:

* cULus for 150603 only

Ordering Information

Ordering Number	Catalog Number	Cable Color	Fuse Size	Packaging
01500603Z	150603	Red	¼" x 1 ¼"	Bulk 100 Pieces
01500604Z	150604	Black	¼" x 1 ¼"	Bulk 100 Pieces

Notes:

For different wire insulation color and length contact LF team.

Additional Information



Resources




Accessories



Samples

19" Loop of 14 AWG Stranded Cu Wire

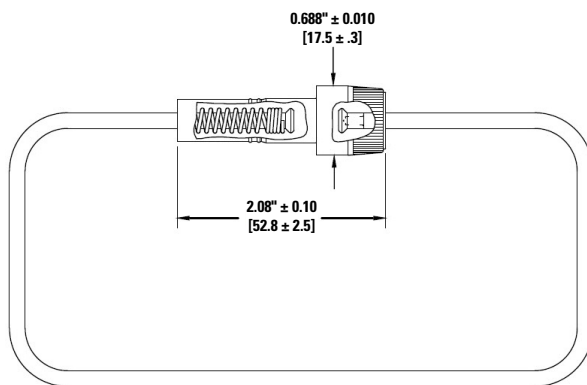

Warning: Electrical Shock. Power must be disconnected prior to handling fuse.

Disclaimer Notice - Information furnished is believed to be accurate and reliable. However, users should independently evaluate the suitability of and test each product selected for their own applications. Littelfuse products are not designed for, and may not be used in, all applications. Read complete Disclaimer Notice at: www.littelfuse.com/disclaimer-electronics.